

Technical data sheet

Adjustable bend element, vertical 60 FT

Item number: 7075200



Adjustable vertical bend element, for all cable tray types with a side height of 60 mm.
RGV 60 adjustable connectors should be ordered separately and in the appropriate quantity.
RGV 60 and SKS 8x16 hexagonal bolts should be ordered separately.



- St

Steel
- FT

Hot-dip galvanised

Master data		
Item number	7075200	
Description 1	Adjustable bend element	
Description 2	vertical	
Manufacturer	OBO	
Dimension	60x200	
Colour	zinc	
Material	Steel	
Surface	Hot-dip galvanised	
Surface standard	DIN EN ISO 1461	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	69.3 kg	
Weight unit	kg/100 pc.	


Technical data sheet

Adjustable bend element, vertical 60 FT

Item number: 7075200



Dimensions

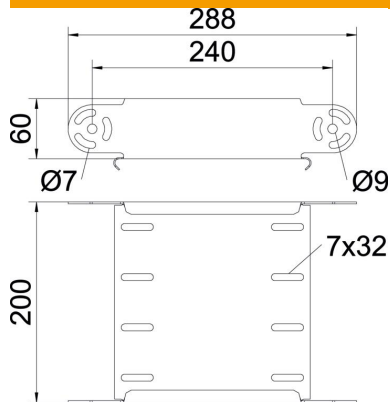

Width	200 mm
Width	8 in
Height	60 mm
Height	2 in
Plate thickness	1 mm
Dimension B	200 mm

Technical data

Bend (angle)	Adjustable
Connector version	Without connectors
Type	Adjustable bend element
Maintain electrical functions	no
Mounting perforation in base	no
NATO hole pattern	no
Change of direction	Vertical, rising/falling
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Type of connector, cable support system	Screwed