

Technical data sheet

Adjustable bend element, vertical 60 A2

Item number: 7075659



Adjustable vertical bend element, for all cable tray types with a side height of 60 mm.
RGV 60 adjustable connectors should be ordered separately and in the appropriate quantity.
Please order RGV 60 and SKS 8x16 hexagonal bolts separately.



- A2 Stainless steel
- 2B Bright, treated

Master data		
Item number	7075659	
Type	RGBEV 650 A2	
Description 1	Adjustable bend element	
Description 2	vertical	
Manufacturer	OBO	
Dimension	60x500	
Colour	stainless steel	
Material	Stainless steel	
Surface	Bright, treated	
Surface standard		
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	136.2 kg	
Weight unit	kg/100 pc.	


Technical data sheet

Adjustable bend element, vertical 60 A2

Item number: 7075659



Dimensions

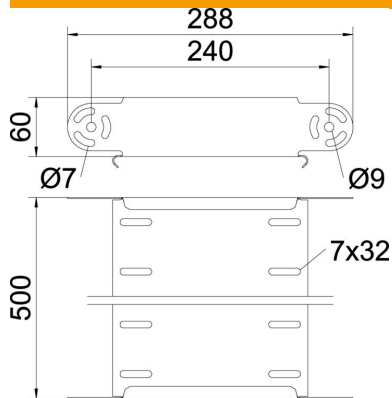

Width	500 mm
Height	60 mm
Plate thickness	1 mm
Dimension B	500 mm

Technical data

Bend (angle)	Adjustable
Connector version	Without connectors
Type	Adjustable bend element
Maintain electrical functions	no
Mounting perforation in base	no
NATO hole pattern	no
Change of direction	Vertical, rising/falling
Rustproof steel, pickled	no
Side perforation	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no
Type of connector, cable support system	Screwed