

Technical data sheet

90° adjustable bend, vertical 60 FT

Item number: 7079508



90° adjustable vertical bend, for all cable tray types with a side height of 60 mm. The bend is shipped in an unmounted state. No additional fastening materials are required.



- St

Steel
- FT

Hot-dip galvanised

Master data		
Item number	7079508	
Description 1	Adjustable bend	
Description 2	vertical	
Manufacturer	OBO	
Dimension	60x500	
Colour	zinc	
Material	Steel	
Surface	Hot-dip galvanised	
Surface standard	DIN EN ISO 1461	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	404 kg	
Weight unit	kg/100 pc.	


Technical data sheet

90° adjustable bend, vertical 60 FT

Item number: 7079508



Dimensions

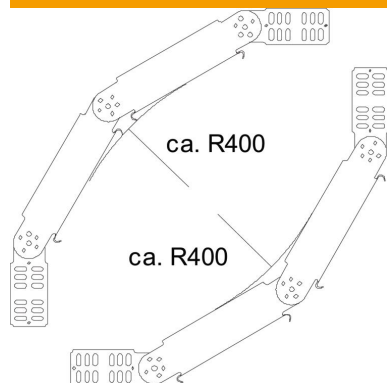

Width	500 mm
Width	20 in
Height	60 mm
Height	2 in
Plate thickness	1 mm
Dimension R	400 mm

Technical data

Bend (angle)	90°
Connector version	Supplied connectors
Type	Adjustable bend_complete
Maintain electrical functions	no
Mounting perforation in base	no
NATO hole pattern	no
Change of direction	Vertical, rising/falling
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Type of connector, cable support system	Screwed