


# Technical data sheet

## Cover, cross-over DD

Item number: 7027844



Cover for cross-over fitting for lockable and screw-on cable trays in indoor and outdoor areas, to protect cables against damage and soiling. Fastening through attachment of the section cover. Suitable for all side heights. The cover can be used with fittings of all side heights.

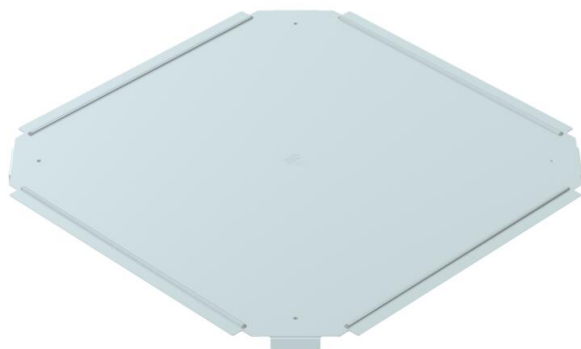

**St** Steel

**DD** Strip galvanised zinc/aluminium, Double Dip

### Master data

Item number	7027844
Type	RKD 300 DD
Description 1	Cover
Description 2	for cross-over
Manufacturer	OBO
Dimension	B300mm
Colour	zinc
Material	Steel
Surface	Strip galvanised zinc/aluminium, Double Dip
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	98 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Cover, cross-over DD

Item number: 7027844



### Dimensions

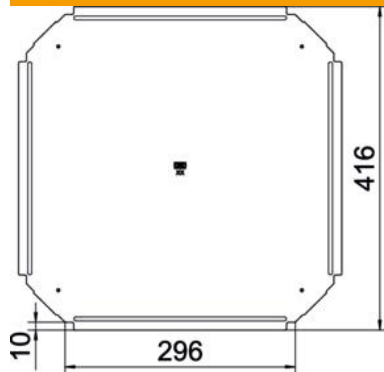

Width	300 mm
Plate thickness	0.75 mm
Dimension B	300 mm

### Technical data

Number of turn buckles	0 St.
Fastening type	On top
Suitable for cable ladder	no
Suitable for cable tray	yes
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C