

Technical data sheet

Cover, cross-over DD

Item number: 7027848



Cover for cross-over fitting for lockable and screw-on cable trays in indoor and outdoor areas, to protect cables against damage and soiling. Fastening through attachment of the section cover. Suitable for all side heights. The cover can be used with fittings of all side heights.



St Steel

DD Strip galvanised zinc/aluminium, Double Dip

Master data

Item number	7027848
Type	RKD 500 DD
Description 1	Cover
Description 2	for cross-over
Manufacturer	OBO
Dimension	B500mm
Colour	zinc
Material	Steel
Surface	Strip galvanised zinc/aluminium, Double Dip
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	294 kg
Weight unit	kg/100 pc.


Technical data sheet

Cover, cross-over DD

Item number: 7027848



Dimensions

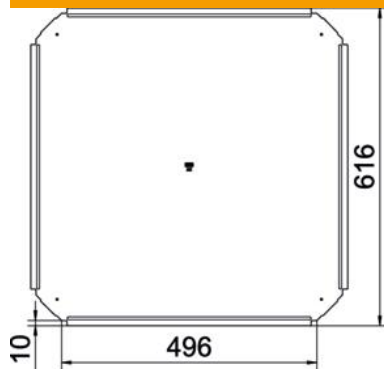

Width	500 mm
Plate thickness	1 mm
Dimension B	500 mm

Technical data

Number of turn buckles	0 St.
Fastening type	On top
Suitable for cable ladder	no
Suitable for cable tray	yes
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C