

Technical data sheet

Cable tray RKS-Magic® 60 FS black

Item number: 6048253



Cable tray with integrated quick-fastening system. Strip-galvanised surface, visible areas powder-coated in jet black (RAL 9005). Continuous side perforations of 7 x 20 mm for the installation of additional connection and mounting components. With 11 mm perforation in the base for direct threaded rod suspension. Usable length 3,000 mm. Magnetic shield insulation without cover 20 dB, with cover 50 dB.



St	Steel
P135	PES135 - Polyester

Master data

Item number	6048253
Type	RKSM 620 FSK SW
Description 1	Cable tray RKSM
Description 2	Magic, quick connector
Manufacturer	OBO
Dimension	60x200x3050
Colour	Jet black; RAL 9005
Material	Steel
Surface	PES135 - Polyester
Surface standard	
Smallest sales unit	6
Unit of quantity	Metre
Weight	146.3 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	4,5945 kg COe / 1 Meter


Technical data sheet

Cable tray RKS-Magic® 60 FS black

Item number: 6048253



Dimensions

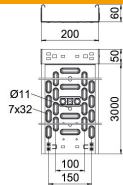

Dimension	60 x 200
Length	3,050 mm
Width	200 mm
Height	60 mm
Plate thickness	0.75 mm
Dimension B	200 mm
Dimension x	100 mm
Dimension y	150 mm
Maß W	200 mm

Technical data

Connector version	Integrated connector
Mounting system fastening type	Floor Ceiling Wall
Walkable	no
Maintain electrical functions	no
With cover	no
Mounting perforation in base	yes
NATO hole pattern	no
Usable cross-section	118 cm ²
Usable cross-section	11800 mm ²
Rustproof steel, pickled	no
Side perforation	yes
Wide-span version	no
Usable length	3000 mm
Type of connector, cable support system	Click fastening

Loads

Insertable support spacings, min.	1 m
Insertable support spacings, max.	2.5 m
Support spacing 1.0 m	1.2 kN/m
Support spacing 1.5 m	1 kN/m
Support spacing 2.0 m	0.55 kN/m
Support spacing 2.5 m	0.4 kN/m