

# Technical data sheet

## Cover, T piece 100 A4

Item number: 6038680



Cover for T piece fitting for lockable and screw-on cable trays in indoor and outdoor areas, to protect cables against damage and soiling. Fastening with pre-mounted sash lock and through attachment of the section cover. Suitable for all side heights.  
The cover can be used with fittings of all side heights.



|    |                 |
|----|-----------------|
| A4 | Stainless steel |
| 2B | Bright, treated |

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 6038680                  |
| Type                               | RTD 100 A4               |
| Description 1                      | Cover                    |
| Description 2                      | for T piece              |
| Manufacturer                       | OBO                      |
| Dimension                          | B100mm                   |
| Colour                             | stainless steel          |
| Material                           | Stainless steel          |
| Surface                            | Bright, treated          |
| Surface standard                   |                          |
| Smallest sales unit                | 1                        |
| Unit of quantity                   | Piece                    |
| Weight                             | 20 kg                    |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,8262 kg CO2e / 1 Piece |


# Technical data sheet

Cover, T piece 100 A4

Item number: 6038680



## Dimensions

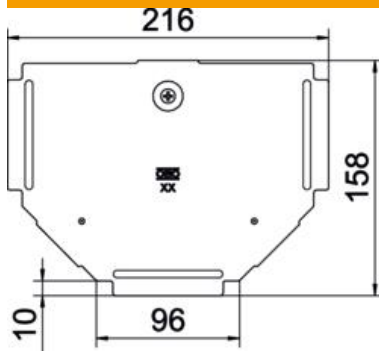

|                 |         |
|-----------------|---------|
| Width           | 100 mm  |
| Plate thickness | 0.75 mm |
| Dimension B     | 100 mm  |

## Technical data

|                                   |           |
|-----------------------------------|-----------|
| Number of turn buckles            | 1 St.     |
| Fastening type                    | Sash lock |
| Suitable for cable ladder         | no        |
| Suitable for cable tray           | yes       |
| Material thickness                | 0.75 mm   |
| Rustproof steel, pickled          | no        |
| Permitted temperature range, max. | 120 °C    |
| Permitted temperature range, min. | -20 °C    |
| Wide-span version                 | no        |