

# Technical data sheet

## Cover, T piece FS

Item number: 6038600



Cover for T piece fitting for lockable and screw-on cable trays in indoor areas, to protect cables against damage and soiling. Fastening with pre-mounted sash lock and through attachment of the section cover. Suitable for all side heights. The cover can be used with fittings of all side heights.



St

Steel

FS

Strip galvanized

### Master data

Item number	6038600
Description 1	Cover
Description 2	for T piece
Manufacturer	OBO
Dimension	B100mm
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	20 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Cover, T piece FS

Item number: 6038600



### Dimensions

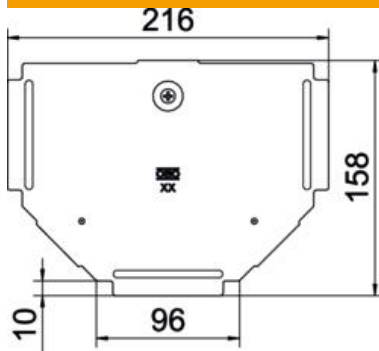

Width	100 mm
Plate thickness	0.75 mm
Dimension B	100 mm

### Technical data

Number of turn buckles	1 St.
Fastening type	Sash lock
Suitable for cable ladder	no
Suitable for cable tray	yes
Material thickness	0.75 mm
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no