

# Technical data sheet

## Cover, T piece 300 A2

Item number: 6038664



Cover for T piece fitting for lockable and screw-on cable trays in indoor and outdoor areas, to protect cables against damage and soiling. Fastening with pre-mounted sash lock and through attachment of the section cover. Suitable for all side heights.  
The cover can be used with fittings of all side heights.



A2	Stainless steel
2B	Bright, treated

### Master data

Item number	6038664
Type	RTD 300 A2
Description 1	Cover
Description 2	for T piece
Manufacturer	OBO
Dimension	B300mm
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	88 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	6,2543 kg CO2e / 1 Piece


# Technical data sheet

Cover, T piece 300 A2

Item number: 6038664



## Dimensions

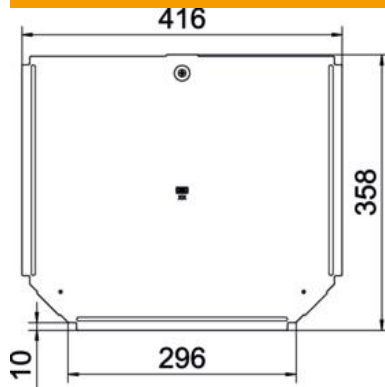

Width	300 mm
Plate thickness	0.75 mm
Dimension B	300 mm

## Technical data

Number of turn buckles	1 St.
Fastening type	Sash lock
Suitable for cable ladder	no
Suitable for cable tray	yes
Material thickness	0.75 mm
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no