

Technical data sheet

Cover, T piece 400 A4

Item number: 6038686



Cover for T piece fitting for lockable and screw-on cable trays in indoor and outdoor areas, to protect cables against damage and soiling. Fastening with pre-mounted sash lock and through attachment of the section cover. Suitable for all side heights.
The cover can be used with fittings of all side heights.



- A4 Stainless steel
- 2B Bright, treated

Master data	
Item number	6038686
Type	RTD 400 A4
Description 1	Cover
Description 2	for T piece
Manufacturer	OBO
Dimension	B400mm
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	140 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	19,0285 kg CO2e / 1 Piece


Technical data sheet

Cover, T piece 400 A4

Item number: 6038686



Dimensions

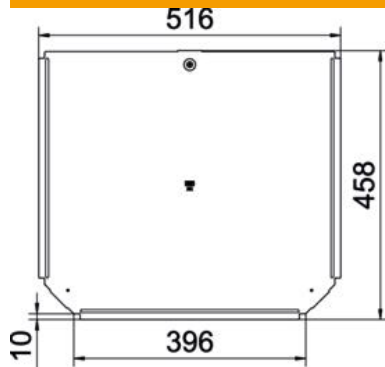

Width	400 mm
Plate thickness	1 mm
Dimension B	400 mm

Technical data

Number of turn buckles	1 St.
Fastening type	Sash lock
Suitable for cable ladder	no
Suitable for cable tray	yes
Material thickness	1 mm
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no