


Technical data sheet

T piece 110/200 A2

Item number: 6038362



T piece for the creation of a horizontal branch, fitting for lock and screw-on cable trays of side height 110 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.

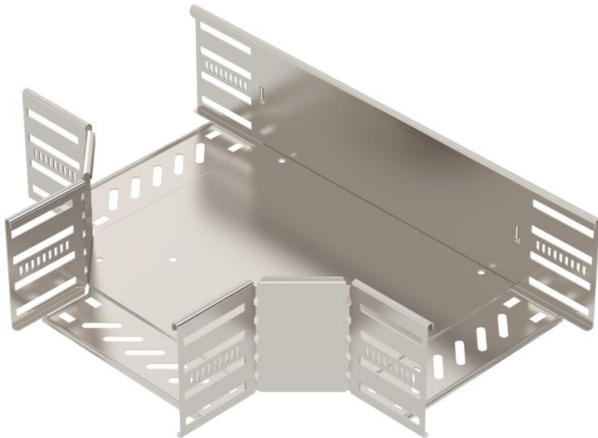

| | |
|----|-----------------|
| A2 | Stainless steel |
| 2B | Bright, treated |

Master data

| | |
|------------------------------------|----------------------------|
| Item number | 6038362 |
| Type | RT 120 A2 |
| Description 1 | T piece |
| Description 2 | for cable tray, horizontal |
| Manufacturer | OBO |
| Dimension | 110x200 |
| Colour | stainless steel |
| Material | Stainless steel |
| Surface | Bright, treated |
| Surface standard | |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 158.4 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 12,2767 kg CO2e / 1 Piece |


Technical data sheet

T piece 110/200 A2

Item number: 6038362



Dimensions

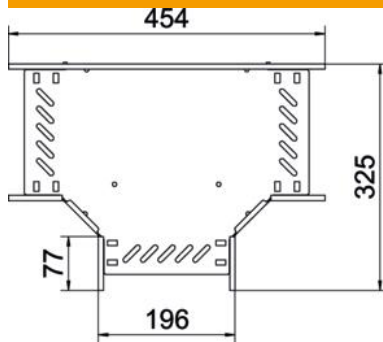

| | |
|-----------------|--------|
| Width | 200 mm |
| Height | 110 mm |
| Plate thickness | 0.8 mm |
| Dimension B | 200 mm |

Technical data

| | |
|---|----------------------|
| Connector version | Integrated connector |
| Maintain electrical functions | no |
| NATO hole pattern | no |
| Rustproof steel, pickled | no |
| Permitted temperature range, max. | 120 °C |
| Permitted temperature range, min. | -20 °C |
| Wide-span version | no |
| Type of connector, cable support system | screwed/clamped |
| Recommended quantity of bolts | 30 St. |
| Rail thickness | 1.25 mm |