

# Technical data sheet


## Reducer/stop-end 60 A4

Item number: 7109953



Reducer and end closure plate for cable trays with side height 60 mm.  
From a width of 150 mm, a perforated lower flange is available.

Including appropriate fastening material.

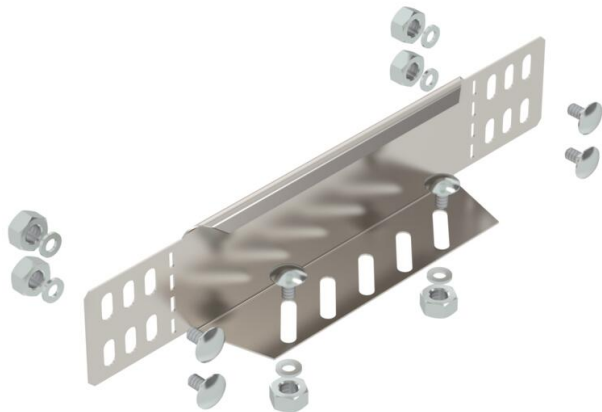

**A4** Stainless steel

**2B** Bright, treated

### Master data

Item number	7109953
Type	RWEB 620 A4
Description 1	Reducer profile/end closure
Description 2	for cable tray
Manufacturer	OBO
Dimension	60x200
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	24 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Reducer/stop-end 60 A4

Item number: 7109953



### Dimensions

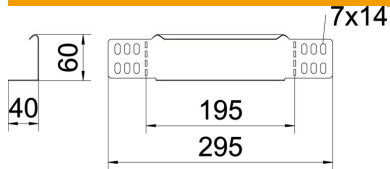

Width	200 mm
Height	60 mm
Height	2 in
Plate thickness	1 mm
Dimension B	195 mm

### Technical data

Connector version	Integrated connector
Maintain electrical functions	no
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no