

Technical data sheet

Aluminium pipe, without thread

Item number: 2046006



Electrical installation pipe without threaded ends to EN 61386-1 for mechanical protection of cables. With burr-free inner wall.



Alu

Aluminium

Master data		
Item number	2046006	
Type	S40W ALU	
Description 1	Aluminium conduit	
Description 2	without thread	
Manufacturer	OBO	
Dimension	Ø40, 3000mm	
Material	Aluminium	
Smallest sales unit	15	
Unit of quantity	Metre	
Weight	45.839 kg	
Weight unit	kg/100 m	
CO Footprint (GWP) Cradle-to-Gate	5,7603 kg COe / 1 Meter	


Technical data sheet

Aluminium pipe, without thread


Item number: 2046006



Dimensions

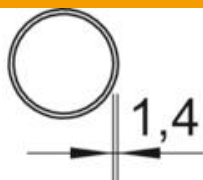

Length	3,000 mm
Dimension D	40 mm
Dimension L	3,000 mm
Dimension m (mm)	M40
Dimension t	1.4 mm

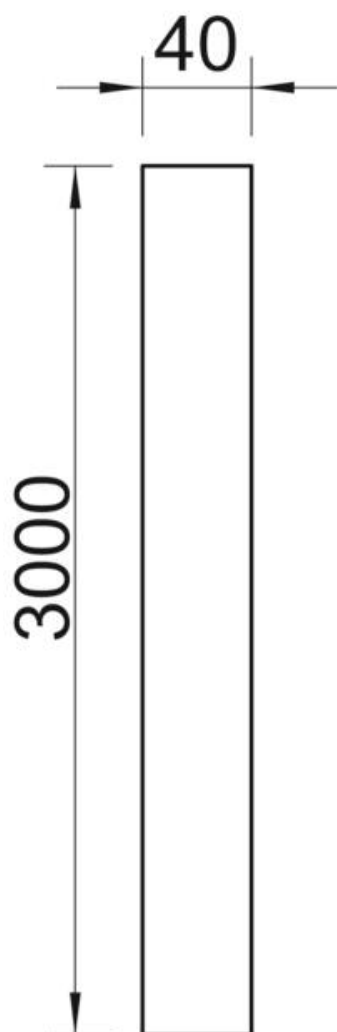

Technical data sheet

Aluminium pipe, without thread

Item number: 2046006



Technical data

Surface-mounted	yes
Pipe version	Rigid without thread
Concrete installation	yes
Bending behaviour	rigid
Pressure resistance	Heavy (1,250 N)
Use temperature, max.	+ 250 °C
Use temperature, min.	- 45 °C
Cavity wall installation	yes
Installation on wood	yes
Installation in the earth	yes
Installation outdoors	yes
Classification code	44561
Machines and system installation	yes
With sleeve	no
Brushed surface	no
Polished surface	no
Impact resistance	Heavy (2.0 kg/300 mm)
Permitted temperature range, max.	250 °C
Permitted temperature range, min.	-45 °C
Underfloor installation (bitumen, hot asphalt)	yes
Underfloor installation (screed)	yes
Concealed	yes