

# Technical data sheet

## Black powder-coated steel bend, without thread

Item number: 2046826



90° bend with moulded sleeves, for electrical installation pipes according to EN 61386-1. With burr-free inner wall.



|             |                         |
|-------------|-------------------------|
| <b>St</b>   | Steel                   |
| <b>PE50</b> | PES50 - Polyester/epoxy |

### Master data

|                                   |                         |
|-----------------------------------|-------------------------|
| Item number                       | 2046826                 |
| Type                              | SBN25 SW                |
| Description 1                     | Conduit plug-in bend    |
| Description 2                     | without thread          |
| Manufacturer                      | OBO                     |
| Dimension                         | Ø25mm                   |
| Colour                            | Jet black; RAL 9005     |
| Material                          | Steel                   |
| Surface                           | PES50 - Polyester/epoxy |
| Surface standard                  |                         |
| Smallest sales unit               | 25                      |
| Unit of quantity                  | Piece                   |
| Weight                            | 24.4 kg                 |
| Weight unit                       | kg/100 pc.              |
| CO Footprint (GWP) Cradle-to-Gate | 0,6157 kg COe / 1 Piece |


# Technical data sheet

## Black powder-coated steel bend, without thread

Item number: 2046826



### Dimensions

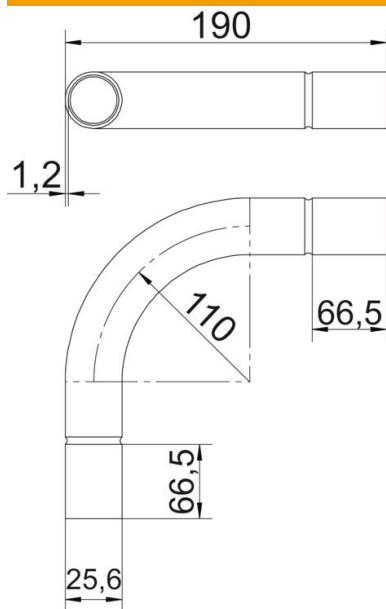

|                  |         |
|------------------|---------|
| Dimension A      | 66.5 mm |
| Dimension B      | 191 mm  |
| Dimension D      | 28 mm   |
| Dimension d      | 25.5 mm |
| Dimension l      | 40 mm   |
| Dimension m (mm) | M25     |
| Dimension R      | 110 mm  |
| Dimension t      | 1.2 mm  |

### Technical data

|                                 |           |
|---------------------------------|-----------|
| Version for                     | Connector |
| Flexible                        | no        |
| For nominal pipe diameter       | 25 mm     |
| Halogen-free                    | no        |
| With inspection opening and lid | no        |
| With sleeve                     | yes       |
| Brushed surface                 | no        |
| Polished surface                | no        |
| Angle of the bend               | 90 °      |
| Two-part                        | no        |