

# Technical data sheet

## Electrogalvanised steel bend, with thread

Item number: 2046784



90° bend for electrical installation pipes according to EN 61386-1 with threaded ends to DIN EN 60423. With burr-free inner wall.  
One connection sleeve is already screwed onto each pipe bend.



|    |                   |
|----|-------------------|
| St | Steel             |
| G  | Electrogalvanized |

### Master data

|                                   |                            |
|-----------------------------------|----------------------------|
| Item number                       | 2046784                    |
| Type                              | SBNM63 G                   |
| Description 1                     | Conduit threaded bend      |
| Description 2                     | with threaded coupler      |
| Manufacturer                      | OBO                        |
| Dimension                         | M63x1,5                    |
| Material                          | Steel                      |
| Surface                           | Electrogalvanized          |
| Surface standard                  | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit               | 3                          |
| Unit of quantity                  | Piece                      |
| Weight                            | 227 kg                     |
| Weight unit                       | kg/100 pc.                 |
| CO Footprint (GWP) Cradle-to-Gate | 6,6438 kg COe / 1 Piece    |


# Technical data sheet

## Electrogalvanised steel bend, with thread

Item number: 2046784



### Dimensions

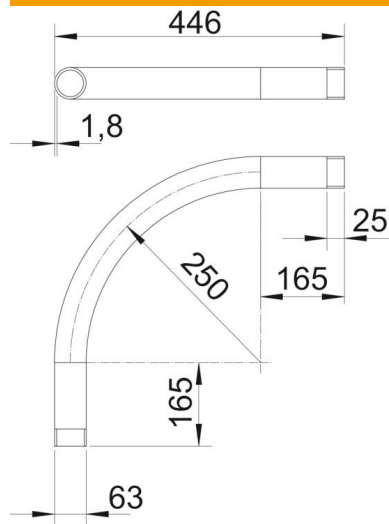

|                  |        |
|------------------|--------|
| Dimension A      | 165 mm |
| Dimension B      | 446 mm |
| Dimension D      | 63 mm  |
| Dimension I      | 25 mm  |
| Dimension m (mm) | M63    |
| Dimension R      | 250 mm |
| Dimension t      | 1.8 mm |

### Technical data

|                                 |         |
|---------------------------------|---------|
| Version for                     | Thread  |
| Flexible                        | no      |
| For nominal pipe diameter       | 63 mm   |
| Thread                          | M63x1,5 |
| Halogen-free                    | no      |
| With inspection opening and lid | no      |
| With sleeve                     | yes     |
| Brushed surface                 | no      |
| Polished surface                | no      |
| Angle of the bend               | 90 °    |
| Two-part                        | no      |