

Technical data sheet

Distribution box, 9 division units, empty, polycarbonate

Item number: 2008868



Small distributor for surface mounting, for the current sub-distribution in interior and exterior areas, according to IEC 439-3. With pre-mounted 35 mm hat profile rail. IP66 protection type and IK08 protection rating. Transparent cover to screw on, with cut-out. Including 4 screw cover caps.

- Protection-insulated for a maximum of 9 division units
 - 8 break-out openings each of Ø 20 mm at the top and bottom
 - 1 combination break-out opening each of Ø 20/25/32 mm at the top and bottom
 - 4 screw cover caps
- Nominal current 63 A
Power loss at 40 K 20.7 W



PC Polycarbonate

Master data

| | |
|-----------------------------------|--------------------------------|
| Item number | 2008868 |
| Type | SDB 09L PC |
| Description 1 | Small distributor |
| Description 2 | no terminal strip, for 9 units |
| Manufacturer | OBO |
| Dimension | 240x191x125 |
| Colour | Light grey; RAL 7035 |
| Material | Polycarbonate |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 108 kg |
| Weight unit | kg/100 pc. |
| CO Footprint (GWP) Cradle-to-Gate | 3,8822 kg COe / 1 Piece |


Technical data sheet

Distribution box, 9 division units, empty, polycarbonate


Item number: 2008868



Dimensions

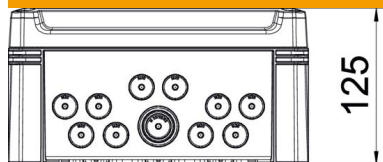

| | |
|--------|--------|
| Length | 241 mm |
| Width | 191 mm |
| Height | 126 mm |

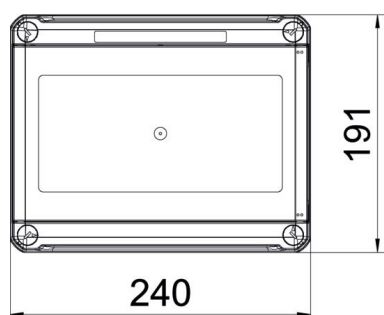

Technical data

| | |
|----------------------------------|------------------------|
| Extension option | yes |
| Number of rows | 1 |
| Cover type | Cover |
| Version, small distributor cover | With cut-out |
| DIN rail | yes |
| Installation location | Protected outdoor area |
| EMC version | no |
| Glow wire test | 850 °C |
| With mounting plate | no |
| With lock | no |
| Mounting type, consumer units | Structure |
| Nominal insulating voltage AC | 1000 V |
| Nominal insulating voltage DC | 1500 V |
| Nominal voltage | 400 V |
| Nominal current | 63 A |
| Protection rating | IP66 |
| Protection rating IK code | IK08 |
| Transparent lid | yes |