

# Technical data sheet

0° socket, Denmark, single

Item number: 6117202



Socket, single 0°, to Danish standard, with increased touch protection, with screw terminals, 2-pin, 16 A 250 V~, with connection terminals to IEC 60884-1.

For installation in Rapid 45 ducts, device installation ducts, installation columns, underfloor systems and Deskboxes.



**PC** Polycarbonate

Master data		
Item number	6117202	
Type	SKS-DK0 RW1	
Description 1	Socket, Danish version	
Manufacturer	OBO	
Dimension	250V, 10/16A	
Colour	Pure white; RAL 9010	
Material	Polycarbonate	
Smallest sales unit	12	
Unit of quantity	Piece	
Weight	3.05 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0101 kg COe / 1 Piece	


# Technical data sheet

0° socket, Denmark, single


Item number: 6117202



## Dimensions

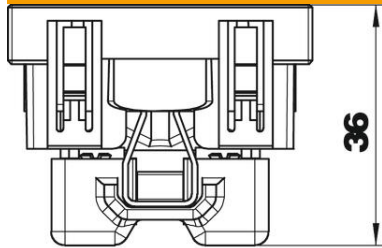

Width	45 mm
Height	45 mm

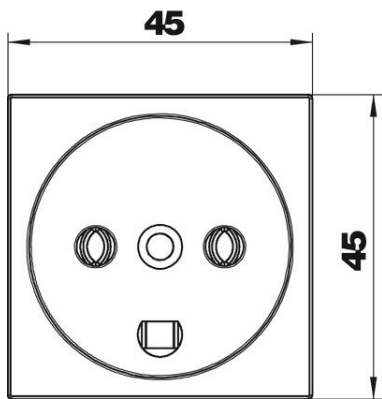

## Technical data

Cover	Central plate
Closable	no
Number of units	1
Number of poles	2
Printed label/coding	Without printing
Version for	Single 0°
Surface version	Not applicable
Version for	Danish norm (earthing pin)
Ejection mechanism	no
Fastening type	Lock
Labelling panel	no
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
increased touch protection	yes
Error current protection	no
For more difficult conditions (according to VDE)	no
Halogen-free	no
Hinged cover	no
Warning light	no
With on/off switch	no
With fine-wire fuse	no
With functional lighting	no

# Technical data sheet

0° socket, Denmark, single

Item number: 6117202



## Technical data

With orientation lighting	no
Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	16 A
Protection rating	Other
Special power supply	Without special power supply
Socket angle	0°
Depth	36 mm
Transparent	no
Rotated central insert	no
Surge protection	no