

Technical data sheet

Hexagonal bolt for trapezoidal fastening TPB 100

Item number: 6418244



Hexagonal bolt for mounting trapezoidal fastening TPB 100, with shaft and thread, including hexagonal nut and 2 washers.



St	Steel
G	Electrogalvanized

Master data

Item number	6418244
Type	SKS 10x110 G
Description 1	Hexagonal screw
Description 2	with nut and washers
Manufacturer	OBO
Dimension	M10x110
Colour	zinc
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	20
Unit of quantity	Piece
Weight	9.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1648 kg CO2e / 1 Piece


Technical data sheet

Hexagonal bolt for trapezoidal fastening TPB 100

Item number: 6418244



Dimensions

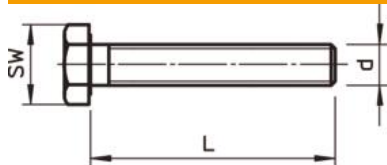

Length	110 mm
Dimension d	0.39 in
Dimension d	10 mm
Dimension L	4.33 in
Dimension L	110 mm

Technical data

Resistance grade	5.6
Thread	M10
Thread metric	10
Thread length	110 mm
Thread increase	1.5 mm
Head shape	Hexagonal
With flange	no
With nut	yes
With washer	yes
WAF	17
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no