


# Technical data sheet

## Hexagonal bolt M10

Item number: 3160757



Hexagonal bolt for universal fastening of construction components. With hexagonal nut and 2 washers.

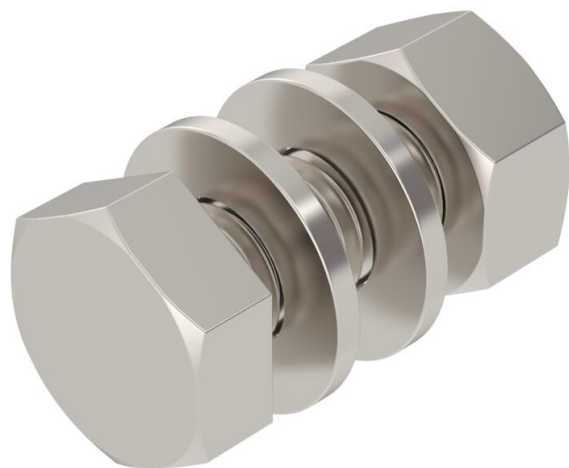

A4 Stainless steel

| Master data                        |                        |
|------------------------------------|------------------------|
| Item number                        | 3160757                |
| Type                               | SKS 10x30 A4           |
| Description 1                      | Hexagonal screw        |
| Description 2                      | with nut and washers   |
| Manufacturer                       | OBO                    |
| Dimension                          | M10x30                 |
| Colour                             | stainless steel        |
| Material                           | Stainless steel        |
| Smallest sales unit                | 20                     |
| Unit of quantity                   | Piece                  |
| Weight                             | 3 kg                   |
| Weight unit                        | kg/100 pc.             |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,221 kg COe / 1 Piece |

# Technical data sheet


## Hexagonal bolt M10

Item number: 3160757



### Dimensions

|             |       |
|-------------|-------|
| Length      | 30 mm |
| Dimension d | 10 mm |
| Dimension L | 30 mm |

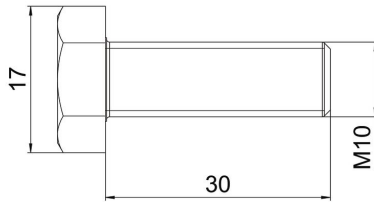

### Technical data

|                  |           |
|------------------|-----------|
| Resistance grade | A4-70     |
| Thread           | M 10 x 30 |
| Thread metric    | 10        |
| Thread type      | Metric    |
| Thread length    | 30 mm     |
| Thread increase  | 1.5 mm    |
| Head shape       | Hexagonal |
| With nut         | yes       |
| With washer      | yes       |
| WAF              | 17        |
| Screw system     | Hexagonal |
| Self-locking     | no        |
| Full thread      | yes       |
| Left thread      | no        |