


Technical data sheet

Hexagonal bolt M10 F

Item number: 3160765



Hexagonal bolt for universal fastening of construction components. With hexagonal nut and 2 washers.

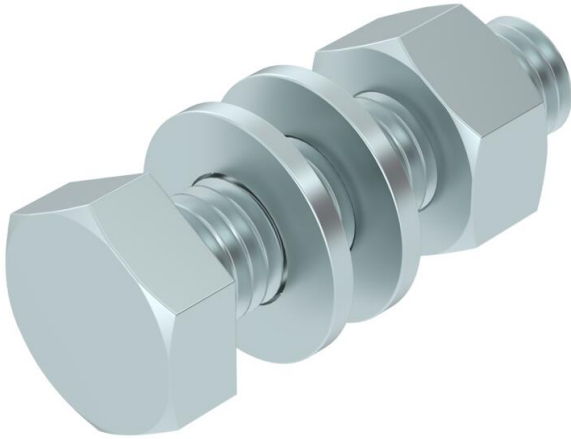

St

Steel

F

Hot galvanized

Master data

Item number	3160765
Type	SKS 10x40 F
Description 1	Hexagonal screw
Description 2	with nut and washers
Manufacturer	OBO
Dimension	M10x40
Colour	zinc
Material	Steel
Surface	Hot galvanized
Surface standard	DIN 267, Teil 10
Smallest sales unit	20
Unit of quantity	Piece
Weight	4.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1233 kg COe / 1 Piece

Technical data sheet


Hexagonal bolt M10 F

Item number: 3160765



Dimensions

Length	40 mm
Dimension d	10 mm
Dimension L	40 mm

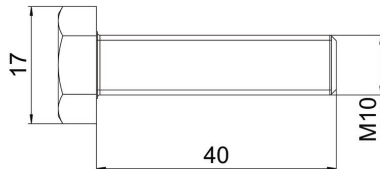

Technical data

Resistance grade	8.8
Thread	M 10 x 40
Thread metric	10
Thread type	Metric
Thread length	40 mm
Thread increase	1.5 mm
Head shape	Hexagonal
With nut	yes
With washer	yes
WAF	17
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no