

# Technical data sheet

## Hexagonal bolt M10 A4

Item number: 6418248



Hexagonal bolt for universal fastening of construction components. With hexagonal nut and 2 washers.



A4	Stainless steel
2B	Bright, treated

Master data		
Item number	6418248	
Type	SKS 10x80 A4	
Description 1	Hexagonal screw	
Description 2	with nut and washers	
Manufacturer	OBO	
Dimension	M10x80	
Colour	stainless steel	
Material	Stainless steel	
Surface	Bright, treated	
Surface standard		
Smallest sales unit	20	
Unit of quantity	Piece	
Weight	7.8 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,3355 kg CO2e / 1 Piece	


# Technical data sheet

## Hexagonal bolt M10 A4

Item number: 6418248



### Dimensions

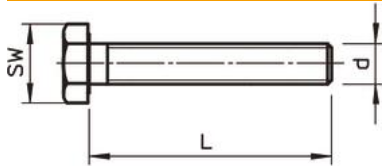

Length	80 mm
Dimension d	10 mm
Dimension L	80 mm

### Technical data

Resistance grade	A4-70
Thread	M 10 x 80
Thread metric	10
Thread type	Metric
Thread length	80 mm
Thread increase	1.5 mm
Head shape	Hexagonal
With flange	no
With nut	yes
With washer	yes
WAF	17
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no