


Technical data sheet

Hexagonal bolt M10 A5

Item number: 6418247



Hexagonal bolt for universal fastening of construction components. With hexagonal nut and 2 washers.

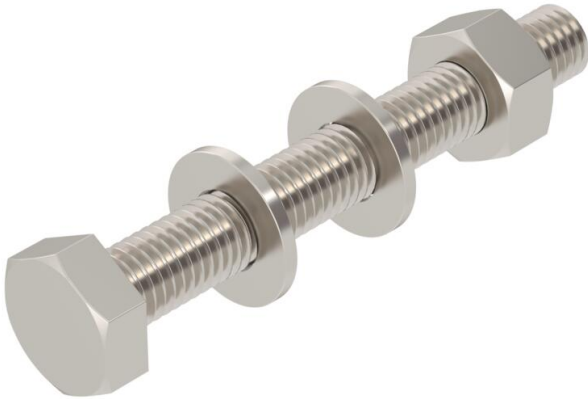


A5

Stainless steel

Master data

| | |
|---------------------|----------------------|
| Item number | 6418247 |
| Type | SKS 10x80 A5 |
| Description 1 | Hexagonal screw |
| Description 2 | with nut and washers |
| Manufacturer | OBO |
| Dimension | M10x80 |
| Colour | stainless steel |
| Material | Stainless steel |
| Smallest sales unit | 20 |
| Unit of quantity | Piece |
| Weight | 7.52 kg |
| Weight unit | kg/100 pc. |

Dimensions

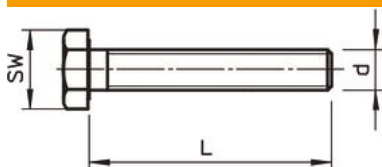

| | |
|-------------|-------|
| Length | 90 mm |
| Dimension d | 10 mm |
| Dimension L | 90 mm |

Technical data sheet

Hexagonal bolt M10 A5

Item number: 6418247



Technical data

| | |
|------------------|-----------|
| Resistance grade | A5-80 |
| Thread | M 10 x 90 |
| Thread metric | 10 |
| Thread type | Metric |
| Thread length | 80 mm |
| Thread increase | 1.5 mm |
| Head shape | Hexagonal |
| With flange | no |
| With nut | yes |
| With washer | yes |
| WAF | 17 |
| Screw system | Hexagonal |
| Self-locking | no |
| Full thread | yes |
| Left thread | no |