


Technical data sheet

Hexagonal bolt M10 F

Item number: 6418250



Hexagonal bolt for universal fastening of construction components. With hexagonal nut and 2 washers.

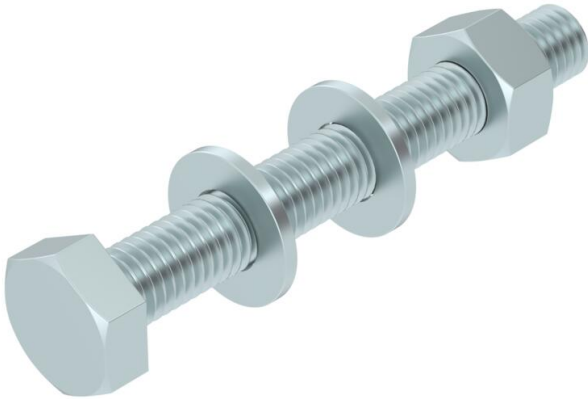

St	Steel
F	Hot galvanized

Master data

Item number	6418250
Type	SKS 10x80 F
Description 1	Hexagonal screw
Description 2	with nut and washers
Manufacturer	OBO
Dimension	M10x80
Colour	zinc
Material	Steel
Surface	Hot galvanized
Surface standard	DIN 267, Teil 10
Smallest sales unit	20
Unit of quantity	Piece
Weight	6.9 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0331 kg COe / 1 Piece


Technical data sheet

Hexagonal bolt M10 F

Item number: 6418250



Dimensions

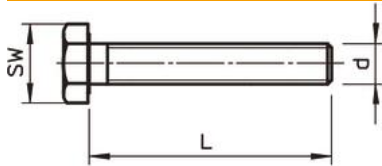

Length	80 mm
Dimension d	10 mm
Dimension L	80 mm

Technical data

Resistance grade	8.8
Thread	M 10 x 80
Thread metric	10
Thread type	Metric
Thread length	80 mm
Thread increase	1.5 mm
Head shape	Hexagonal
With flange	no
With nut	yes
With washer	yes
WAF	17
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no