

# Technical data sheet

## Hexagonal bolt M10 A4

Item number: 6418256



Hexagonal bolt for universal fastening of construction components. With hexagonal nut and 2 washers.



**A4** Stainless steel

**2B** Bright, treated

### Master data

Item number	6418256
Type	SKS 10x90 A4
Description 1	Hexagonal screw
Description 2	with nut and washers
Manufacturer	OBO
Dimension	M10x90
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	20
Unit of quantity	Piece
Weight	7.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3568 kg CO2e / 1 Piece


# Technical data sheet

## Hexagonal bolt M10 A4

Item number: 6418256



### Dimensions

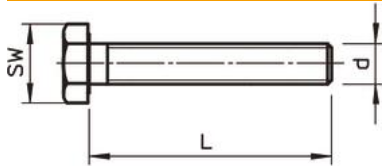

Length	90 mm
Dimension d	10 mm
Dimension L	90 mm

### Technical data

Resistance grade	A4-70
Thread	M 10 x 90
Thread metric	10
Thread type	Metric
Thread length	90 mm
Thread increase	1.5 mm
Head shape	Hexagonal
With flange	no
With nut	yes
With washer	yes
WAF	17
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no