

Technical data sheet

Hexagonal bolt M12 A2

Item number: 6418368



Hexagonal bolt for universal fastening of construction components. With hexagonal nut and 2 washers.



A2 Stainless steel

2B Bright, treated

Master data

Item number	6418368
Type	SKS 12x100 A2
Description 1	Hexagonal screw
Description 2	with nut and washers
Manufacturer	OBO
Dimension	M12x100
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	20
Unit of quantity	Piece
Weight	12 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,6068 kg CO2e / 1 Piece


Technical data sheet

Hexagonal bolt M12 A2

Item number: 6418368



Dimensions

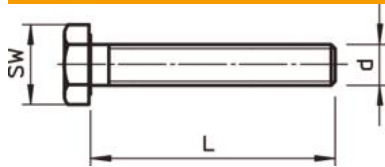

Length	100 mm
Dimension d	0.47 in
Dimension d	12 mm
Dimension L	3.93 in
Dimension L	100 mm

Technical data

Resistance grade	A2-70
Thread	M 12 x 100
Thread metric	12
Thread type	Metric
Thread length	100 mm
Thread increase	1.75 mm
Head shape	Hexagonal
With flange	no
With nut	yes
With washer	yes
WAF	19
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no