

Technical data sheet

Hexagonal bolt M12 A2

Item number: 6418376



Hexagonal bolt for universal fastening of construction components. With hexagonal nut and 2 washers.



A2	Stainless steel
2B	Bright, treated

Master data		
Item number	6418376	
Type	SKS 12x110 A2	
Description 1	Hexagonal screw	
Description 2	with nut and washers	
Manufacturer	OBO	
Dimension	M12x110	
Colour	stainless steel	
Material	Stainless steel	
Surface	Bright, treated	
Surface standard		
Smallest sales unit	20	
Unit of quantity	Piece	
Weight	14.5 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,6528 kg CO2e / 1 Piece	


Technical data sheet

Hexagonal bolt M12 A2

Item number: 6418376



Dimensions

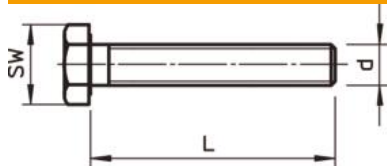

Length	110 mm
Dimension d	0.47 in
Dimension d	12 mm
Dimension L	4.33 in
Dimension L	110 mm

Technical data

Resistance grade	A2-70
Thread	M 12 x 110
Thread metric	12
Thread type	Metric
Thread length	110 mm
Thread increase	1.75 mm
Head shape	Hexagonal
With flange	no
With nut	yes
With washer	yes
WAF	19
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no