

# Technical data sheet

## Hexagonal bolt M12 A4

Item number: 6418274



Hexagonal bolt for universal fastening of construction components. With hexagonal nut and 2 washers.




**A4** Stainless steel

**2B** Bright, treated

### Master data

Item number	6418274
Type	SKS 12x110 A4
Description 1	Hexagonal screw
Description 2	with nut and washers
Manufacturer	OBO
Dimension	M12x110
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	20
Unit of quantity	Piece
Weight	12.38 kg
Weight unit	kg/100 pc.

### Dimensions

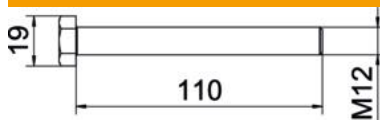

Length	110 mm
Dimension d	12 mm
Dimension L	110 mm

# Technical data sheet

## Hexagonal bolt M12 A4

Item number: 6418274



### Technical data

Resistance grade	A4-70
Thread	M 12 x 110
Thread metric	12
Thread type	Metric
Thread length	110 mm
Thread increase	1.75 mm
Head shape	Hexagonal
With flange	no
With nut	yes
With washer	yes
WAF	19
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no