

Technical data sheet

Hexagonal bolt M12 F

Item number: 6418317



Hexagonal bolt for universal fastening of construction components. With hexagonal nut and 2 washers.



St	Steel
F	Hot galvanized

Master data

Item number	6418317
Type	SKS 12x110 F
Description 1	Hexagonal screw
Description 2	with nut and washers
Manufacturer	OBO
Dimension	M12x110
Colour	zinc
Material	Steel
Surface	Hot galvanized
Surface standard	DIN 267, Teil 10
Smallest sales unit	20
Unit of quantity	Piece
Weight	14.5 kg
Weight unit	kg/100 pc.


Technical data sheet

Hexagonal bolt M12 F

Item number: 6418317



Dimensions

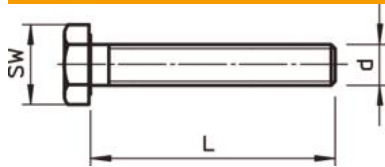

Length	110 mm
Dimension d	0.47 in
Dimension d	12 mm
Dimension L	4.33 in
Dimension L	110 mm

Technical data

Resistance grade	8.8
Thread	M 12 x 110
Thread metric	12
Thread type	Metric
Thread length	110 mm
Thread increase	1.75 mm
Head shape	Hexagonal
With flange	no
With nut	yes
With washer	yes
WAF	19
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no