

Technical data sheet

Hexagonal bolt M12 A2

Item number: 6418279



Hexagonal bolt for universal fastening of construction components. With hexagonal nut and 2 washers.



A2	Stainless steel
2B	Bright, treated

Master data	
Item number	6418279
Type	SKS 12x80 A2
Description 1	Hexagonal screw
Description 2	with nut and washers
Manufacturer	OBO
Dimension	M12x80
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	20
Unit of quantity	Piece
Weight	10.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4856 kg CO2e / 1 Piece


Technical data sheet

Hexagonal bolt M12 A2

Item number: 6418279



Dimensions

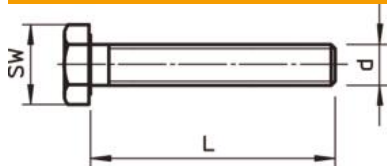

Length	80 mm
Dimension d	0.47 in
Dimension d	12 mm
Dimension L	3.14 in
Dimension L	80 mm

Technical data

Resistance grade	A2-70
Thread	M 12 x 80
Thread metric	12
Thread type	Metric
Thread length	80 mm
Thread increase	1.75 mm
Head shape	Hexagonal
With flange	no
With nut	yes
With washer	yes
WAF	19
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no