

Technical data sheet

Hexagonal bolt DIN 933

Item number: 3156790



Hexagonal bolt according to DIN 933 with metric thread. Resistance grade at least 8.8.



St	Steel
ZL	Zinc slat

Master data

Item number	3156790
Type	SKS M12x40 ZL
Description 1	Hexagonal screw
Available from	01.04.2019
Manufacturer	OBO
Dimension	M12x40
Material	Steel
Surface	Zinc slat
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	4.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1055 kg COe / 1 Piece


Technical data sheet

Hexagonal bolt DIN 933

Item number: 3156790



Dimensions

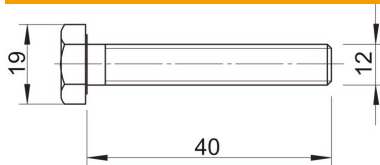

Length	40 mm
Dimension d	12 mm
Dimension L	40 mm

Technical data

Resistance grade	8.8
Thread	M12
Thread metric	12
Thread type	Metric
Thread length	40 mm
Head shape	Hexagonal
With flange	no
With nut	no
With washer	no
WAF	19
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no