

Technical data sheet


Control T piece with thread

Item number: 2047605



Die-cast aluminium T piece, with internal thread, for mounting in pipe sections as a junction.

Removable cover for easier cable routing and later checking.

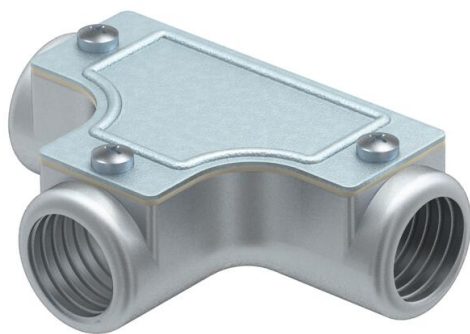

**AIG** Cast aluminium

| Master data                       |                         |  |
|-----------------------------------|-------------------------|--|
| Item number                       | 2047605                 |  |
| Type                              | SKTM20W ALU             |  |
| Description 1                     | Control T piece         |  |
| Description 2                     | with thread             |  |
| Manufacturer                      | OBO                     |  |
| Dimension                         | M20x1,5                 |  |
| Material                          | Cast aluminium          |  |
| Smallest sales unit               | 5                       |  |
| Unit of quantity                  | Piece                   |  |
| Weight                            | 13.5 kg                 |  |
| Weight unit                       | kg/100 pc.              |  |
| CO Footprint (GWP) Cradle-to-Gate | 1,7186 kg COe / 1 Piece |  |


# Technical data sheet

## Control T piece with thread

Item number: 2047605



### Dimensions

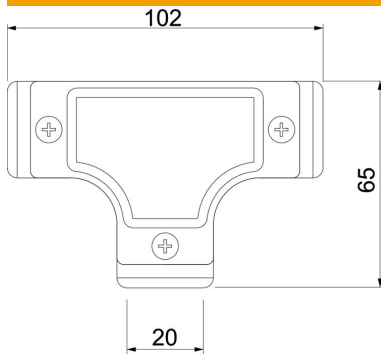

|                  |         |
|------------------|---------|
| Length           | 102 mm  |
| Dimension D      | 65 mm   |
| Dimension L      | 102 mm  |
| Dimension m (mm) | M20x1,5 |

### Technical data

|                  |         |
|------------------|---------|
| Version for      | Thread  |
| Thread           | M20x1,5 |
| Size             | 20      |
| Halogen-free     | no      |
| Brushed surface  | no      |
| Polished surface | no      |