

Technical data sheet

Heavy-duty vertical cable ladder SLM 50, 3 m C40

Item number: 6010539



The vertical ladder with a 50 mm side height is shipped in an unmounted state and must be screwed together on the construction site.

The appropriate clamp clip for the C profile rung is type 2056U.



St Steel

FT Hot-dip galvanised

Master data

Item number	6010539
Description 1	Vertical ladder heavyweight
Description 2	with C 40 rung
Manufacturer	OBO
Dimension	900x3000
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	3
Unit of quantity	Metre
Weight	765.833 kg
Weight unit	kg/100 m


Technical data sheet

Heavy-duty vertical cable ladder SLM 50, 3 m C40

Item number: 6010539



Dimensions

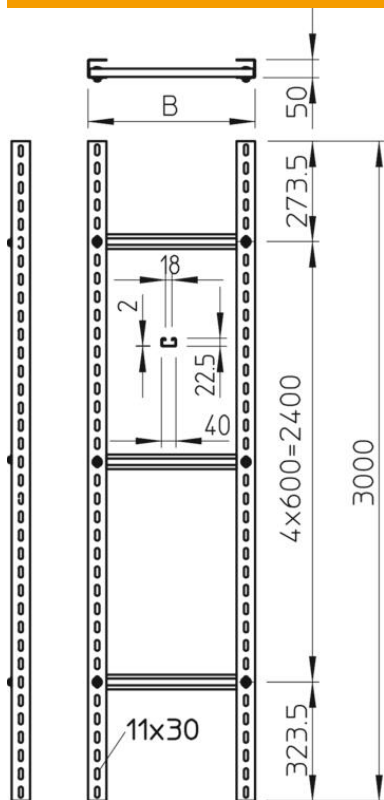

Length	3,000 mm
Width	900 mm
Height	50 mm
Dimension B	900 mm
Rung slot dimension	18.00

Technical data

Side wall version	U profile
Version of the rungs	Profile unperforated
Maintain electrical functions	no
Rustproof steel, pickled	no
Side perforation	yes
Rung distance	600 mm
Rail thickness	2.5 mm