

# Technical data sheet

## Industrial vertical cable ladder, 6 m C40

Item number: 6013406



Vertical ladder of side height 80 mm with screwed-in rungs.  
The vertical ladder is shipped in an unmounted state.  
The appropriate clamp clip is type 2056U.



St

Steel

FT

Hot-dip galvanised

### Master data

|                     |                            |
|---------------------|----------------------------|
| Item number         | 6013406                    |
| Description 1       | Vertical ladder industrial |
| Description 2       | with C 40 rung             |
| Manufacturer        | OBO                        |
| Dimension           | 400x6000                   |
| Colour              | zinc                       |
| Material            | Steel                      |
| Surface             | Hot-dip galvanised         |
| Surface standard    | DIN EN ISO 1461            |
| Smallest sales unit | 6                          |
| Unit of quantity    | Metre                      |
| Weight              | 1286.667 kg                |
| Weight unit         | kg/100 m                   |


# Technical data sheet

## Industrial vertical cable ladder, 6 m C40

Item number: 6013406



### Dimensions

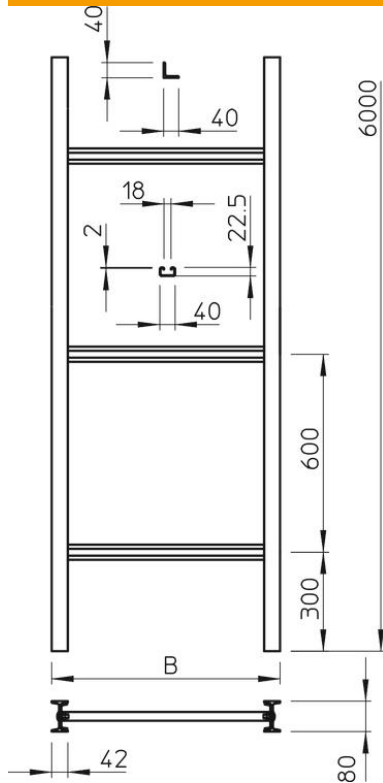

|                     |          |
|---------------------|----------|
| Length              | 6,000 mm |
| Width               | 400 mm   |
| Height              | 80 mm    |
| Dimension B         | 400 mm   |
| Rung slot dimension | 18.00    |

### Technical data

|                               |                      |
|-------------------------------|----------------------|
| Side wall version             | I profile            |
| Version of the rungs          | Profile unperforated |
| Maintain electrical functions | no                   |
| Rustproof steel, pickled      | no                   |
| Side perforation              | yes                  |
| Rung distance                 | 600 mm               |