

Technical data sheet

Industrial vertical cable ladder, 6 m W40

Item number: 6013902



Vertical ladder of side height 80 mm with screwed-in rungs.
The vertical ladder is shipped in an unmounted state.
The appropriate U clamp is type 2056W.



St

Steel

FT

Hot-dip galvanised

Master data

Item number	6013902
Type	SLS 80 W40 10 FT
Description 1	Vertical ladder industrial
Description 2	with W 40 rung
Manufacturer	OBO
Dimension	1000x6000
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	6
Unit of quantity	Metre
Weight	1627.167 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	35,183 kg CO2e / 1 Meter


Technical data sheet

Industrial vertical cable ladder, 6 m W40

Item number: 6013902



Dimensions

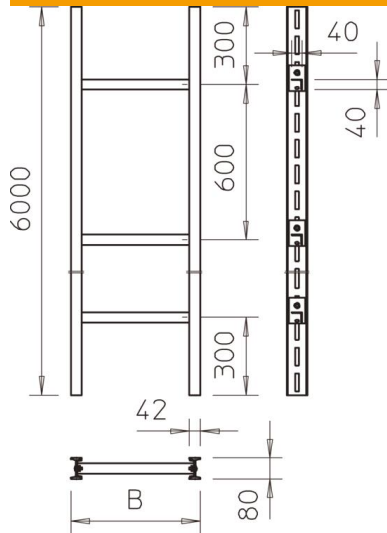

Length	6,000 mm
Width	1,000 mm
Height	80 mm
Dimension B	1,000 mm

Technical data

Side wall version	I profile
Version of the rungs	Profile unperforated
Maintain electrical functions	no
Rustproof steel, pickled	no
Side perforation	yes
Rung distance	600 mm