


# Technical data sheet

## T piece 110 FT

Item number: 6225364



T piece, horizontal, with welded rung for all cable ladder types of 110 mm side height.  
Connectors should be ordered separately and in the appropriate quantity.

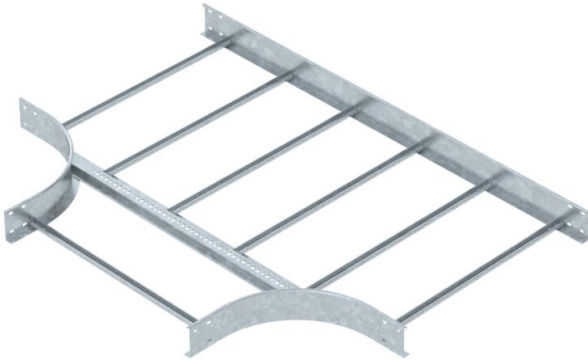

|    |                    |
|----|--------------------|
| St | Steel              |
| FT | Hot-dip galvanised |

### Master data

|                     |                    |
|---------------------|--------------------|
| Item number         | 6225364            |
| Type                | SLT 1180 R3 FT     |
| Description 1       | T piece            |
| Description 2       | for cable ladder   |
| Manufacturer        | OBO                |
| Dimension           | 110x800            |
| Colour              | zinc               |
| Material            | Steel              |
| Surface             | Hot-dip galvanised |
| Surface standard    | DIN EN ISO 1461    |
| Smallest sales unit | 1                  |
| Unit of quantity    | Piece              |
| Weight              | 1579.5 kg          |
| Weight unit         | kg/100 pc.         |


# Technical data sheet

## T piece 110 FT

Item number: 6225364



### Dimensions

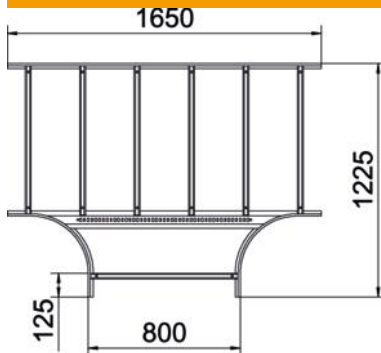

|             |        |
|-------------|--------|
| Width       | 800 mm |
| Height      | 110 mm |
| Dimension B | 800 mm |
| Dimension R | 300 mm |

### Technical data

|                               |                      |
|-------------------------------|----------------------|
| Version of the rungs          | Profile unperforated |
| Side rail version             | Flat profile         |
| Connector version             | Without connectors   |
| Type                          | Exit symmetrical     |
| Maintain electrical functions | no                   |
| Rustproof steel, pickled      | no                   |
| Wide-span version             | no                   |
| Rail thickness                | 2 mm                 |