


Technical data sheet

90° bend with Z rung, FT

Item number: 7099224



90° bend for shipbuilding cable ladders, type SLZ L, with side height of 35 mm with welded, perforated Z rungs.
Connectors should be ordered separately and in the appropriate quantity.

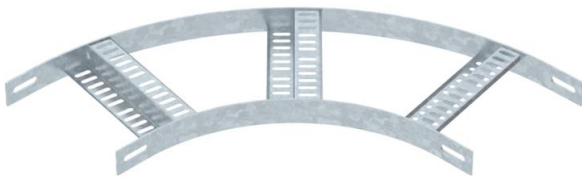

St	Steel
FT	Hot-dip galvanised

Master data

Item number	7099224
Type	SLZB L 90 200 FT
Description 1	90° bend
Description 2	with Z-rung
Manufacturer	OBO
Dimension	B206mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	153.3 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	3,6937 kg CO2e / 1 Piece


Technical data sheet

90° bend with Z rung, FT

Item number: 7099224



Dimensions

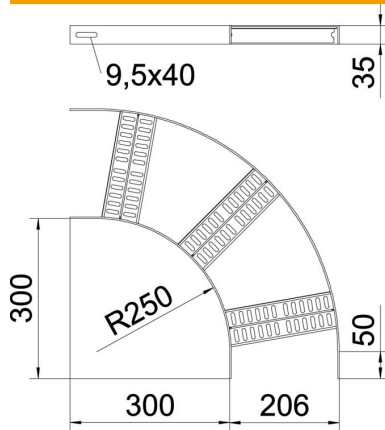

Width	200 mm
Height	35 mm

Technical data

Bend (angle)	90°
Version of the rungs	Profile perforated
Side rail version	Flat profile
Connector version	Without connectors
Maintain electrical functions	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Hinged	no
Side perforation	no
Wide-span version	no
Rail thickness	3 mm