

Technical data sheet

Skirting trunking SL 20110

Item number: 6132274



SL skirting trunking for covered cable routing in internal areas. The colour of the trunking bases can vary depending on the production method.
With snap-on cover and base, with base perforation for direct wall mounting.
Change the direction with the fittings and close the trunking ends with end pieces. Service outlet for installing power and data technology.
Tested according to DIN EN 50085-1 and DIN EN 50085-2-1.
Base and cover packed as a set in a box. The trunking couplings must be ordered separately.



PVC Polyvinylchloride

Master data

| | |
|------------------------------------|--------------------------|
| Item number | 6132274 |
| Type | SL 20110 rws |
| Description 1 | Skirting trunking |
| Description 2 | SL Set 20x110 9010 |
| Manufacturer | OBO |
| Colour | Pure white; RAL 9010 |
| Material | Polyvinylchloride |
| Smallest sales unit | 2 |
| Unit of quantity | Metre |
| Weight | 70.1 kg |
| Weight unit | kg/100 m |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,5681 kg CO2e / 1 Meter |


Technical data sheet

Skirting trunking SL 20110

Item number: 6132274



Dimensions

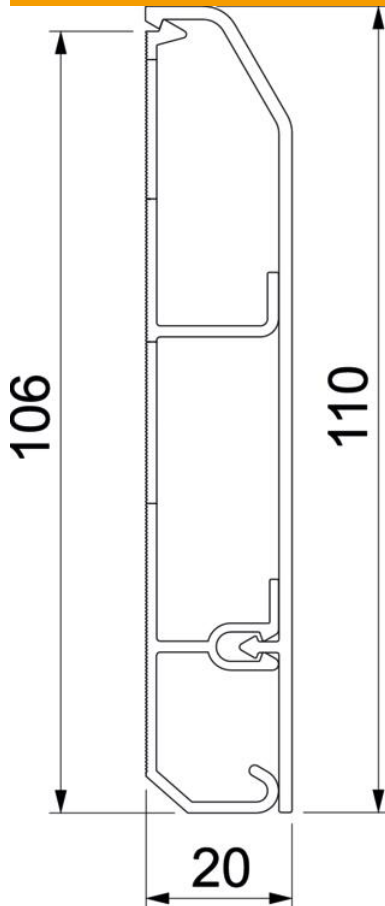

| | |
|--------|----------|
| Length | 2,000 mm |
| Width | 110 mm |
| Height | 20 mm |

Technical data

| | |
|-----------------------------------|----------------------|
| Number of fixed partitions | 2 |
| Decoration | Without |
| Cover sealing lip | Without |
| Halogen-free | no |
| With carpet strip | no |
| Mounting perforation in base | yes |
| Usable cross-section | 1350 mm ² |
| Protection rating | IP40 |
| Protective film | no |
| Protection rating IK code | IK06 |
| Permitted temperature range, max. | 60 °C |
| Permitted temperature range, min. | -5 °C |