

Technical data sheet

Internal corner SL IE20110

Item number: 6132259



Internal corner as a fitting for changing the direction of the skirting trunking.

Internal corner for snapping on to the base to conceal cuts.



PVC Polyvinylchloride

Master data		
Item number	6132259	
Type	SL IE20110 rws	
Description 1	Internal corner	
Description 2	SL 20x110 9010	
Manufacturer	OBO	
Colour	Pure white; RAL 9010	
Material	Polyvinylchloride	
Smallest sales unit	10	
Unit of quantity	Piece	
Weight	1.06 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0305 kg CO2e / 1 Piece	


Technical data sheet

Internal corner SL IE20110


Item number: 6132259



Dimensions

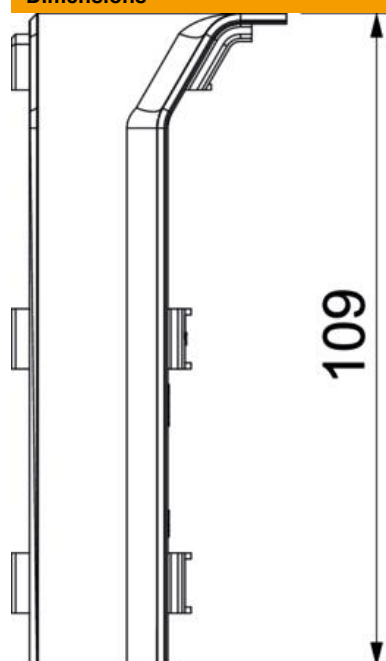

Length	46 mm
Width	46 mm
Height	109 mm

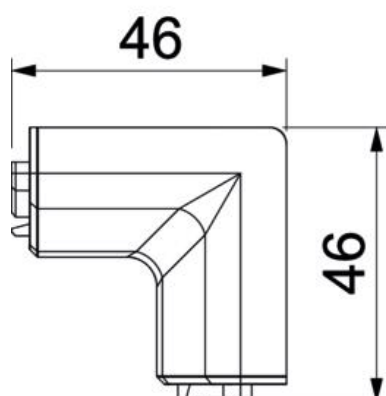

Technical data sheet

Internal corner SL IE20110

Item number: 6132259



Technical data

Version for	Hood fitting
Decoration	Without
Cover sealing lip	Without
Halogen-free	no
With carpet strip	no
Protection rating	IP40
Protection rating IK code	IK06
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, min.	90 mm