

Technical data sheet

Internal corner SL IE2070

Item number: 6132253



Internal corner as a fitting for changing the direction of the skirting trunking.
Internal corner for snapping on to the base to conceal cuts.



PVC Polyvinylchloride

Master data	
Item number	6132253
Description 1	Internal corner
Description 2	SL 20x70 9010
Manufacturer	OBO
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	1.26 kg
Weight unit	kg/100 pc.


Technical data sheet

Internal corner SL IE2070


Item number: 6132253



Dimensions

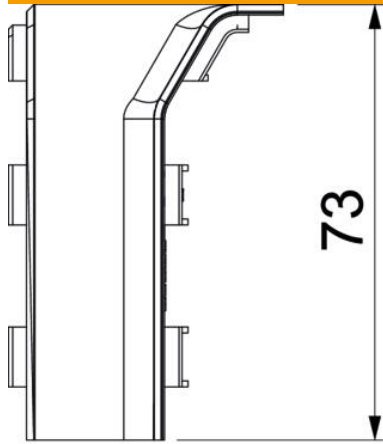

Length	46 mm
Width	46 mm
Height	73 mm

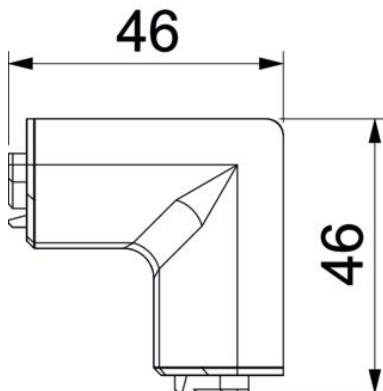

Technical data

Version for	Hood fitting
Decoration	Without
Cover sealing lip	Without
Halogen-free	no
With carpet strip	no
Protection rating	IP40
Protection rating IK code	IK06
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, min.	90 mm