

# Technical data sheet

## Rung C30, perforated FT

Item number: 6009987



Perforated rung, C profile version, for subsequent installation and use in cable ladders. To be screwed on. Fastening material must be ordered separately.



**St** Steel

**FT** Hot-dip galvanised

### Master data

|                     |                          |
|---------------------|--------------------------|
| Item number         | 6009987                  |
| Type                | SPR C30 595 FT           |
| Description 1       | Rung, perforated         |
| Description 2       | material thickness 1.5mm |
| Manufacturer        | OBO                      |
| Dimension           | L=595mm                  |
| Colour              | zinc                     |
| Material            | Steel                    |
| Surface             | Hot-dip galvanised       |
| Surface standard    | DIN EN ISO 1461          |
| Smallest sales unit | 1500                     |
| Unit of quantity    | Piece                    |
| Weight              | 41.6 kg                  |
| Weight unit         | kg/100 pc.               |


# Technical data sheet

Rung C30, perforated FT

Item number: 6009987



## Dimensions

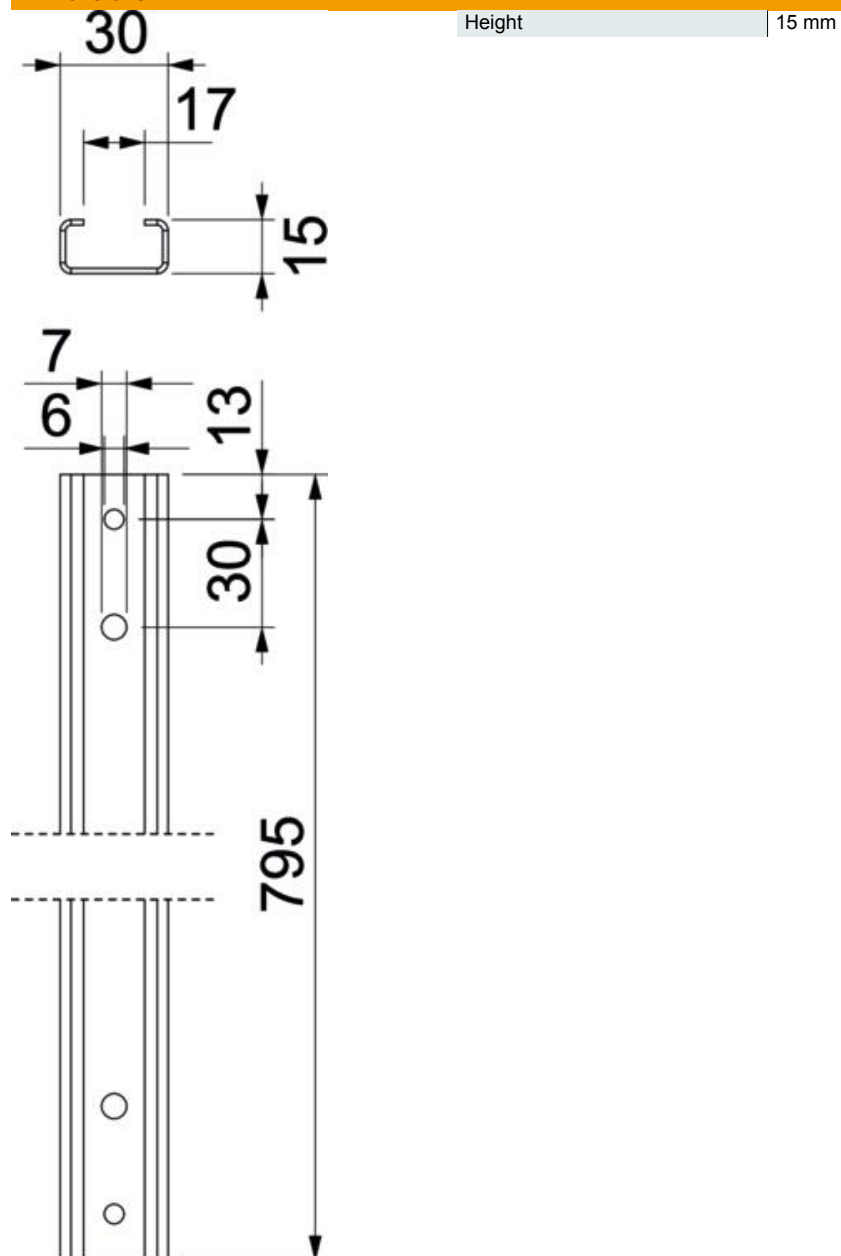

## Technical data

|            |       |
|------------|-------|
| Slot width | 17 mm |
|------------|-------|