


Technical data sheet

Modul 45connect® connector part adapter, black

Item number: 6117196

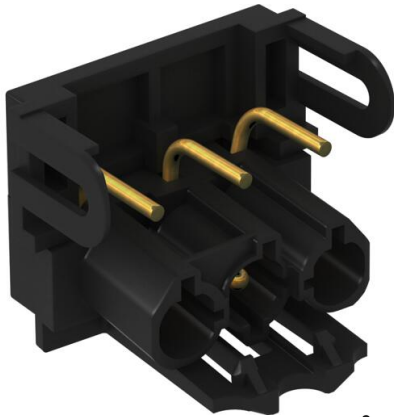

Connector part adapter, U-shaped, for connection to an STD-D0C / STD-D3C or STD-F0C / STD-F3C socket from the side, for VL extension cable with Wieland connector GST 18i 3p.



PA Polyamide

Master data		
Item number	6117196	
Type	STA-SKS SU1 SW	
Description 1	Connect. part adapter,U-shaped	
Description 2	GST 18i 3p, Modul 45connect	
Manufacturer	OBO	
Colour	Black	
Material	Polyamide	
Smallest sales unit	10	
Unit of quantity	Piece	
Weight	1.19 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0544 kg CO2e / 1 Piece	

Dimensions		
	Length	35 mm
	Width	40 mm
	Height	29 mm

Technical data sheet

Modul 45connect® connector part adapter, black

Item number: 6117196



Technical data

Type of locking	Integrated in plug connector
Version of the device connection	Connector
Built-in variants	Installation part/plug connection
Colour of the coding/contact insert	Black
Colour of the separate adapter	Black
Thread connection dimension	No threaded connection
Halogen-free	yes
Contact material	CuZn
Mechanical encoding	yes
Angle of inclination, max.	0 °
Angle of inclination, min.	0 °
Nominal voltage	250 V
Nominal current	16 A
Surface treatment of the contacts	Tin-plated
Pin labelling	L, N, PE
Pole number	3
Protection rating	IP20
Direction of insertion	Straight
Plug-in system	GST18