

# Technical data sheet

0° socket, India, combination IA6A3-EURO, single

Item number: 6120728



Socket, single 0°, India, combination of India/Euro plug, with increased touch protection, with screw terminals, 2-pin, 6 A, 250 V~.



PC Polycarbonate

## Master data

|                                    |                                |
|------------------------------------|--------------------------------|
| Item number                        | 6120728                        |
| Type                               | STD-IN0M RW1                   |
| Description 1                      | Socket 0°, single              |
| Description 2                      | S. Africa/India, double/triple |
| Manufacturer                       | OBO                            |
| Dimension                          | 250V, 6A                       |
| Colour                             | Pure white; RAL 9010           |
| Material                           | Polycarbonate                  |
| Smallest sales unit                | 1                              |
| Unit of quantity                   | Piece                          |
| Weight                             | 5.3 kg                         |
| Weight unit                        | kg/100 pc.                     |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0101 kg COe / 1 Piece        |


# Technical data sheet

0° socket, India, combination IA6A3-EURO, single

Item number: 6120728



## Dimensions

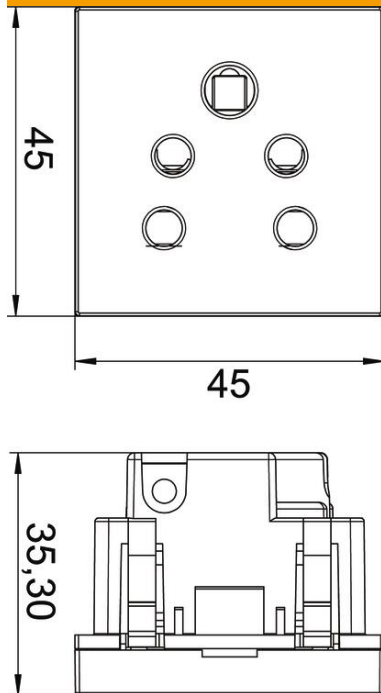

## Technical data

|                                                  |                              |
|--------------------------------------------------|------------------------------|
| Cover                                            | Central plate                |
| Closable                                         | no                           |
| Number of units                                  | 1                            |
| Number of poles                                  | 2                            |
| Printed label/coding                             | Without printing             |
| Version for                                      | single 0°                    |
| Surface version                                  | Not applicable               |
| Version for                                      | South Africa/India           |
| Fastening type                                   | Lock                         |
| Operating temperature, max.                      | 40 °C                        |
| Operating temperature, min.                      | -5 °C                        |
| increased touch protection                       | yes                          |
| For more difficult conditions (according to VDE) | no                           |
| With on/off switch                               | no                           |
| With functional lighting                         | no                           |
| With orientation lighting                        | no                           |
| Nominal voltage                                  | 250 V                        |
| Nominal current                                  | 6 A                          |
| Protection rating                                | Other                        |
| Special power supply                             | Without special power supply |
| Transparent                                      | no                           |