

Technical data sheet

0° socket, India, 5 A, single

Item number: 6120726



Socket, single 0°, India, conforming to BS 546, with increased touch protection, with screw terminals, 2-pin, 5 A, 250 V~.



PC Polycarbonate

Master data

Item number	6120726
Type	STD-IN0 RW1
Description 1	Socket 0°, single
Description 2	South Africa/India, triple
Manufacturer	OBO
Dimension	250V, 5A
Colour	Pure white; RAL 9010
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	4.3 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0179 kg COe / 1 Piece


Technical data sheet

0° socket, India, 5 A, single

Item number: 6120726



Dimensions

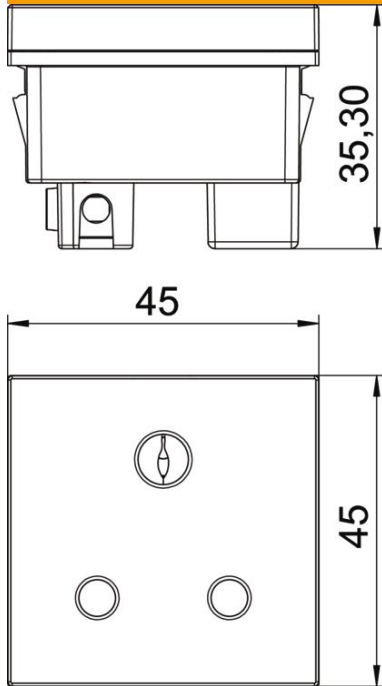

Technical data

Cover	Central plate
Closable	no
Number of units	1
Number of poles	2
Printed label/coding	Without printing
Version for	Single 0°
Surface version	Not applicable
Version for	South Africa/India
Fastening type	Lock
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
increased touch protection	yes
For more difficult conditions (according to VDE)	no
With on/off switch	no
With functional lighting	no
With orientation lighting	no
Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	5 A
Protection rating	Other
Special power supply	Without special power supply
Transparent	no