

Technical data sheet

90° socket, Italy, single

Item number: 6120746



Single 90° socket, Italy P17/11, with increased touch protection, with screw terminals, 2-pin, 16 A, 250 V~.



PC Polycarbonate

Master data		
Item number	6120746	
Type	STD-IT0 RW0.5	
Description 1	Socket 0°, single	
Description 2	Italy , P17 / 11	
Manufacturer	OBO	
Dimension	250V, 10/16A	
Colour	Pure white; RAL 9010	
Material	Polycarbonate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	2.6 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0091 kg COe / 1 Piece	


Technical data sheet

90° socket, Italy, single

Item number: 6120746



Dimensions

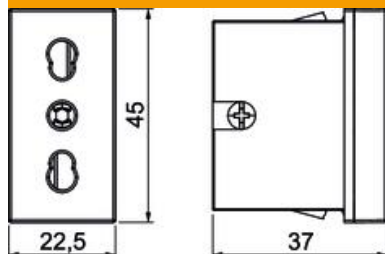

Width	22.5 mm
Height	45 mm

Technical data

Cover	Central plate
Closable	no
Connection type	Screw terminal
Number of units	1
Number of switchable sockets	0
Number of poles	2
Printed label/coding	Without printing
Version for	Italy
Surface version	Matt
Version for	Italian type P17/11
Ejection mechanism	no
Fastening type	Lock
Labelling panel	no
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
Error current protection	no
For more difficult conditions (according to VDE)	no
Halogen-free	yes
Hinged cover	no
Warning light	no
With on/off switch	no
With fine-wire fuse	no
With functional lighting	no
With orientation lighting	no
Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	16 A
Protection rating	Other
Special power supply	Without special power supply
Socket angle	0°
Depth	37 mm
Transparent	no
Rotated central insert	no
Surge protection	no