


Technical data sheet

0° socket, Italy, single, full module width

Item number: 6120761



Single 0° socket, Italy P17/11, with increased touch protection, with screw terminals, 2-pin, 16 A, 250 V~.

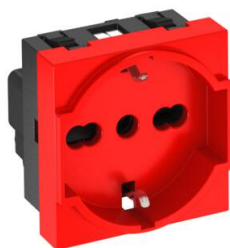

PC

Polycarbonate

Master data

Item number	6120761
Type	STD-IT0 SRO1
Description 1	Socket 0°, single
Description 2	Italy P40, flex. cable
Manufacturer	OBO
Dimension	45x45x39
Colour	Signal red; RAL 3001
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	4.004 kg
Weight unit	kg/100 pc.


Technical data sheet

0° socket, Italy, single, full module width

Item number: 6120761



Dimensions

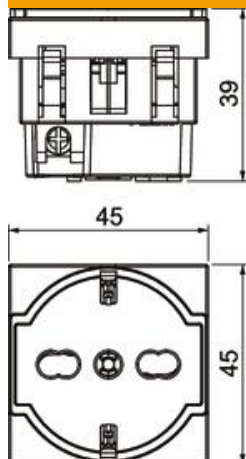

Width	22.5 mm
Height	45 mm

Technical data

Cover	Central plate
Closable	no
Connection type	Screw terminal
Number of units	1
Number of switchable sockets	0
Number of poles	2
Printed label/coding	Without printing
Version for	Italy
Surface version	Matt
Version for	Italian type P17/11
Ejection mechanism	no
Fastening type	Lock
Labelling panel	no
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
Error current protection	no
For more difficult conditions (according to VDE)	no
Halogen-free	yes
Hinged cover	no
Warning light	no
With on/off switch	no
With fine-wire fuse	no
With functional lighting	no
With orientation lighting	no
Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	16 A
Protection rating	Other
Special power supply	Without special power supply
Depth	37 mm
Transparent	no