


# Technical data sheet

0° socket with switch, South Africa/India, 16 A, single

Item number: 6120734



Socket, single 0°, with switch, South Africa/India, conforming to BS 546, with increased touch protection, with screw terminals, 2-pin, 16 A, 250 V~.

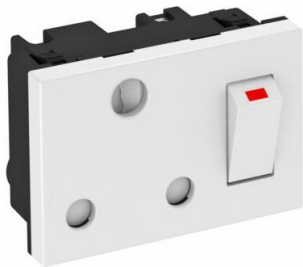

PC Polycarbonate

Master data	
Item number	6120734
Type	STD-SA0G RW1.5
Description 1	Socket 0°, single
Description 2	South Africa/India, w. switch
Manufacturer	OBO
Dimension	250V, 16A
Colour	Pure white; RAL 9010
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	6.7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0193 kg COe / 1 Piece


# Technical data sheet

0° socket with switch, South Africa/India, 16 A, single

Item number: 6120734



## Dimensions

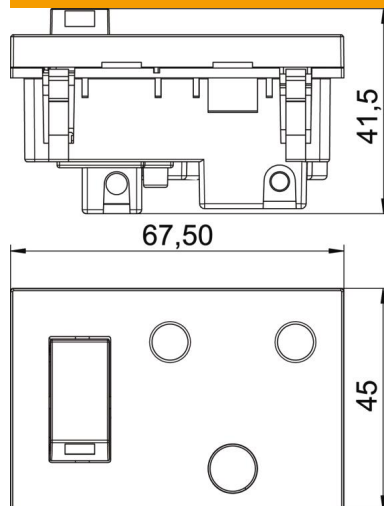

## Technical data

Cover	Central plate
Closable	no
Number of units	1
Number of poles	2
Printed label/coding	Without printing
Version for	Single 0°
Surface version	Not applicable
Version for	South Africa/India
Fastening type	Lock
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
increased touch protection	yes
For more difficult conditions (according to VDE)	no
With on/off switch	yes
With functional lighting	no
With orientation lighting	no
Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	16 A
Protection rating	Other
Special power supply	Without special power supply
Transparent	no