

Technical data sheet

Electrogalvanised steel sleeve, without thread

Item number: 2046857



Accessory part: plug-in sleeve for the connections between electrical installation pipes. With burr-free inner wall.



St	Steel
G	Electrogalvanized

Master data

Item number	2046857
Type	SV32W G
Description 1	Conduit plug-in coupler
Description 2	without thread
Manufacturer	OBO
Dimension	Ø32mm
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	50
Unit of quantity	Piece
Weight	7.2 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,1814 kg COe / 1 Piece


Technical data sheet

Electrogalvanised steel sleeve, without thread

Item number: 2046857



Dimensions

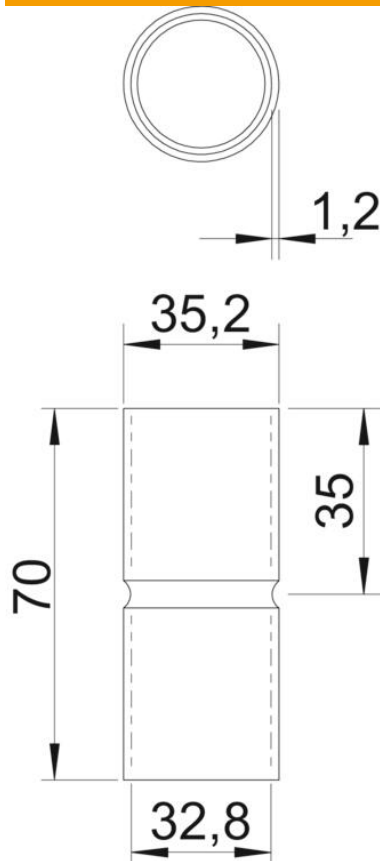

Length	70 mm
Dimension D	35.2 mm
Dimension d	32.8 mm
Dimension L	70 mm
Dimension l	35 mm
Dimension m (mm)	M32
Dimension t	1.2 mm

Technical data

Version for for pipe diameter	Connector 32 mm
Size	32
Halogen-free	yes
With inspection opening and lid	no
Brushed surface	no
Polished surface	no
Permitted temperature range, max.	400 °C
Permitted temperature range, min.	-45 °C
Two-part	no