

Technical data sheet

Electrogalvanised steel sleeve, without thread

Item number: 2046859



Accessory part: plug-in sleeve for the connections between electrical installation pipes. With burr-free inner wall.



St	Steel
G	Electrogalvanized

Master data

Item number	2046859
Type	SV50W G
Description 1	Conduit plug-in coupler
Description 2	without thread
Manufacturer	OBO
Dimension	Ø50mm
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	10
Unit of quantity	Piece
Weight	20 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,4166 kg COe / 1 Piece


Technical data sheet

Electrogalvanised steel sleeve, without thread

Item number: 2046859



Dimensions

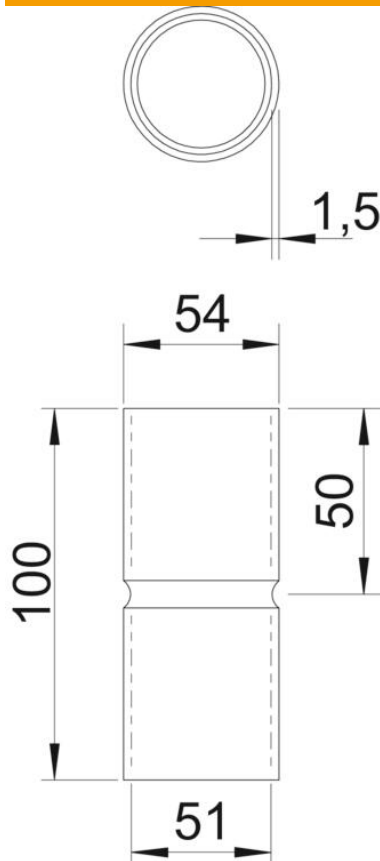

Length	100 mm
Dimension D	54 mm
Dimension d	51 mm
Dimension L	100 mm
Dimension l	50 mm
Dimension m (mm)	M50
Dimension t	1.5 mm

Technical data

Version for	Connector
for pipe diameter	50 mm
Size	50
Halogen-free	yes
With inspection opening and lid	no
Brushed surface	no
Polished surface	no
Permitted temperature range, max.	400 °C
Permitted temperature range, min.	-45 °C
Two-part	no