

# Technical data sheet

## Hot-dip galvanised steel sleeve, without thread

Item number: 2046626



Accessory part: plug-in sleeve for the connections between electrical installation pipes. With burr-free inner wall.



|    |                    |
|----|--------------------|
| St | Steel              |
| FT | Hot-dip galvanised |

### Master data

|                                   |                         |
|-----------------------------------|-------------------------|
| Item number                       | 2046626                 |
| Type                              | SV63W FT                |
| Description 1                     | Conduit plug-in coupler |
| Description 2                     | without thread          |
| Manufacturer                      | OBO                     |
| Dimension                         | Ø63mm                   |
| Material                          | Steel                   |
| Surface                           | Hot-dip galvanised      |
| Surface standard                  | DIN EN ISO 1461         |
| Smallest sales unit               | 5                       |
| Unit of quantity                  | Piece                   |
| Weight                            | 22 kg                   |
| Weight unit                       | kg/100 pc.              |
| CO Footprint (GWP) Cradle-to-Gate | 0,7433 kg COe / 1 Piece |


# Technical data sheet

## Hot-dip galvanised steel sleeve, without thread

Item number: 2046626



### Dimensions

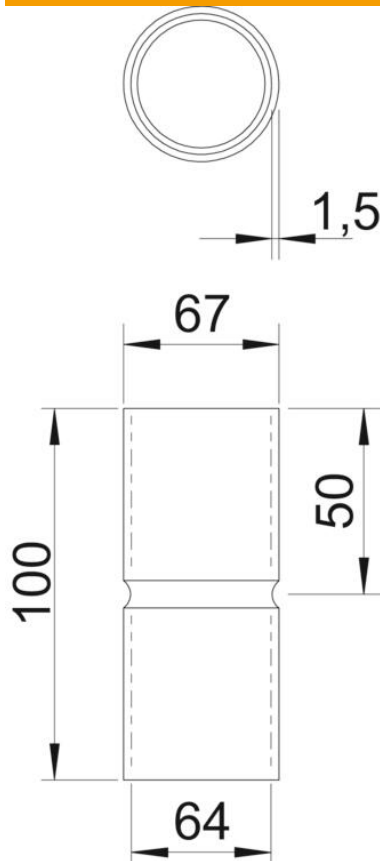

|                  |        |
|------------------|--------|
| Length           | 100 mm |
| Dimension D      | 67 mm  |
| Dimension d      | 63 mm  |
| Dimension L      | 100 mm |
| Dimension l      | 50 mm  |
| Dimension m (mm) | M63    |
| Dimension t      | 1.5 mm |

### Technical data

|                                   |           |
|-----------------------------------|-----------|
| Version for                       | Connector |
| for pipe diameter                 | 63 mm     |
| Size                              | 63        |
| Halogen-free                      | yes       |
| With inspection opening and lid   | no        |
| Brushed surface                   | no        |
| Polished surface                  | no        |
| Permitted temperature range, max. | 400 °C    |
| Permitted temperature range, min. | -45 °C    |
| Two-part                          | no        |