

Technical data sheet

Electrogalvanised steel sleeve, with thread

Item number: 2046878



Accessory part: coupling with thread according to EN 60423 to connect electrical installation pipes and 90° bends.



St	Steel
G	Electrogalvanized

Master data

Item number	2046878
Type	SVM32W G
Description 1	Conduit threaded coupler
Description 2	with thread
Manufacturer	OBO
Dimension	M32x1,5
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	50
Unit of quantity	Piece
Weight	8.8 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,2198 kg COe / 1 Piece


Technical data sheet

Electrogalvanised steel sleeve, with thread

Item number: 2046878



Dimensions

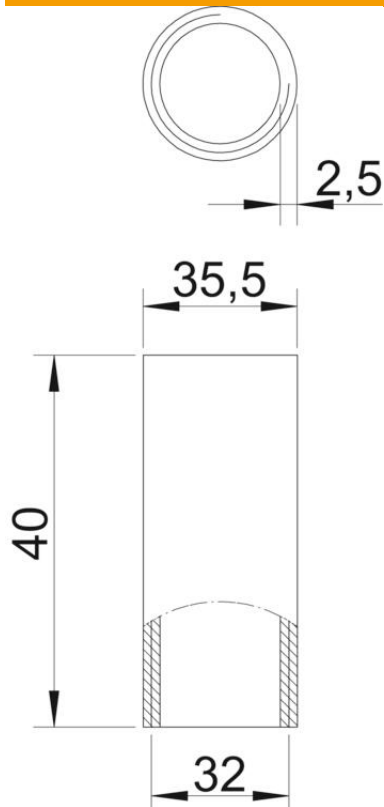

Dimension D	35.5 mm
Dimension d	32 mm
Dimension L	45 mm
Dimension m (mm)	M32
Dimension t	2.5 mm

Technical data

Version for	Thread
for pipe diameter	32 mm
Thread	M32x1,5
Size	32
Halogen-free	no
With inspection opening and lid	no
Brushed surface	no
Polished surface	no
Permitted temperature range, max.	400 °C
Permitted temperature range, min.	-45 °C
Two-part	no